
 



5350.00


4000.00


TOP OVERLAY

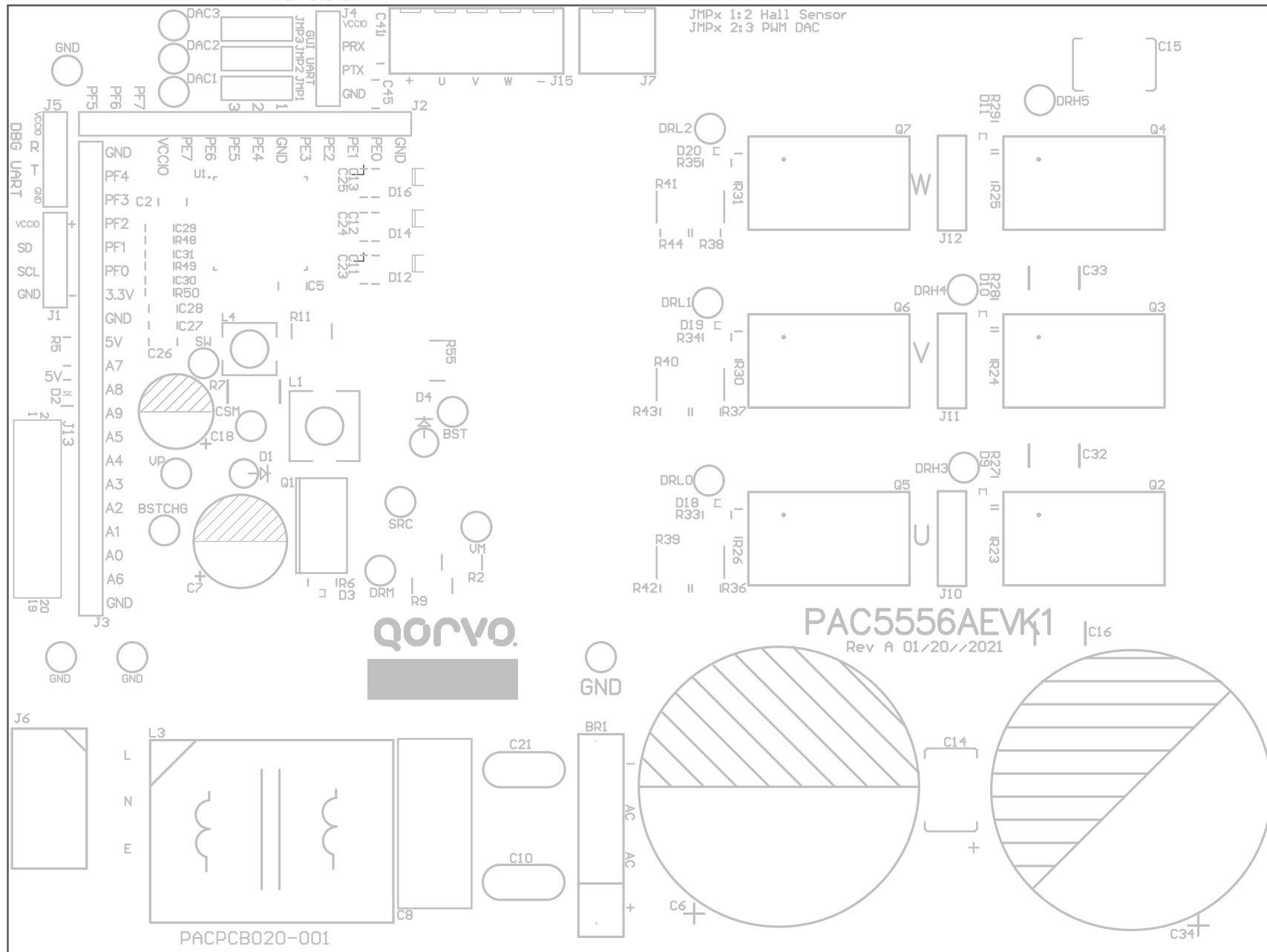



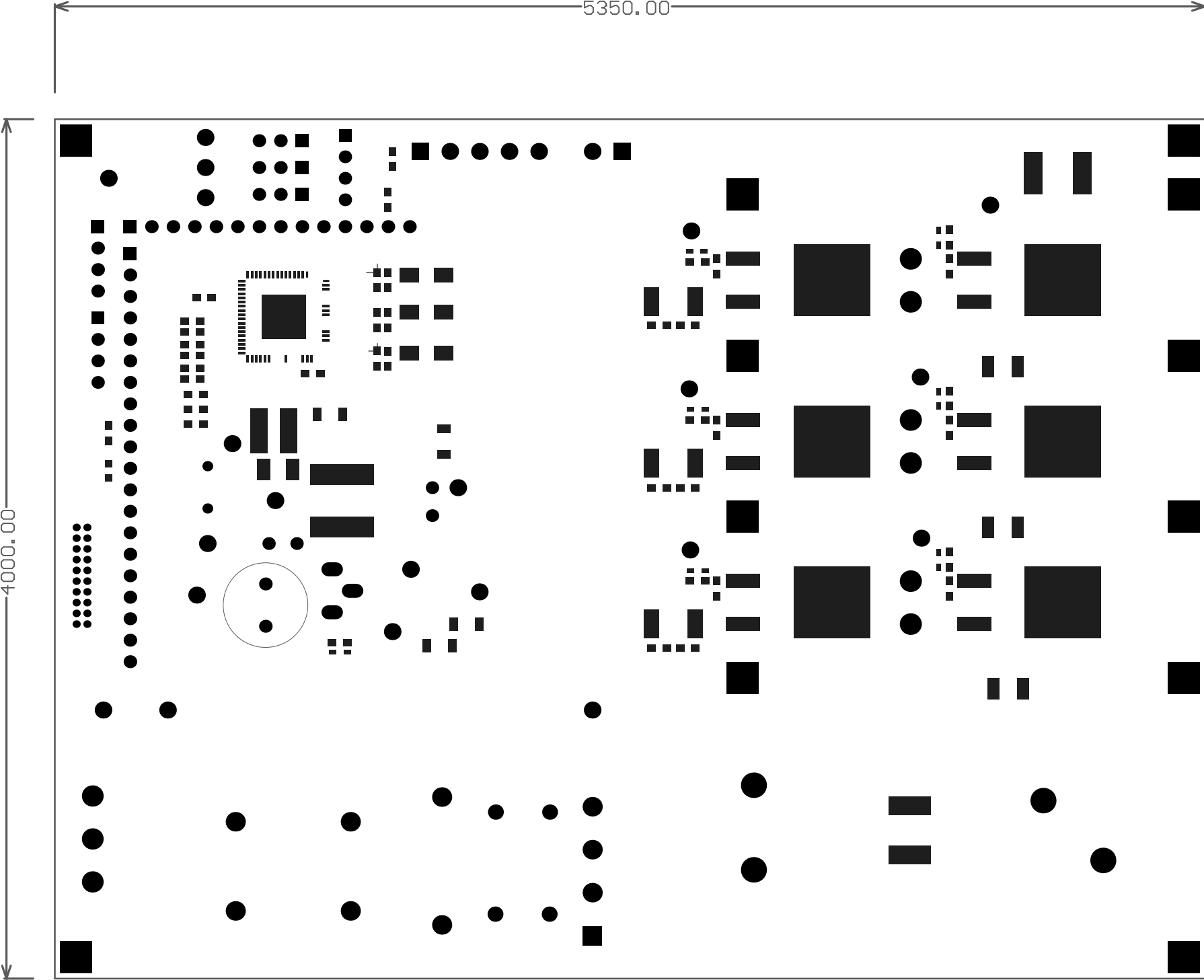

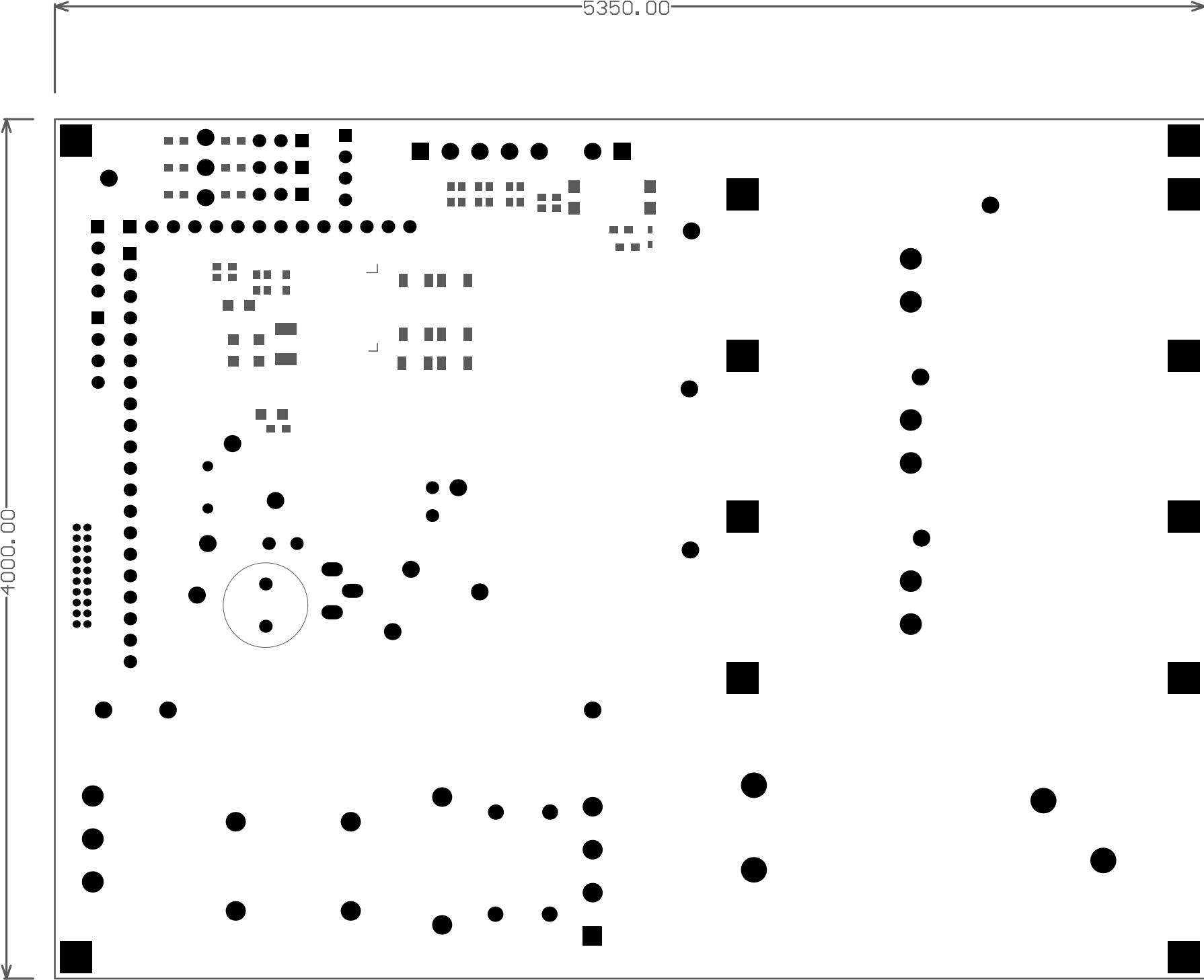

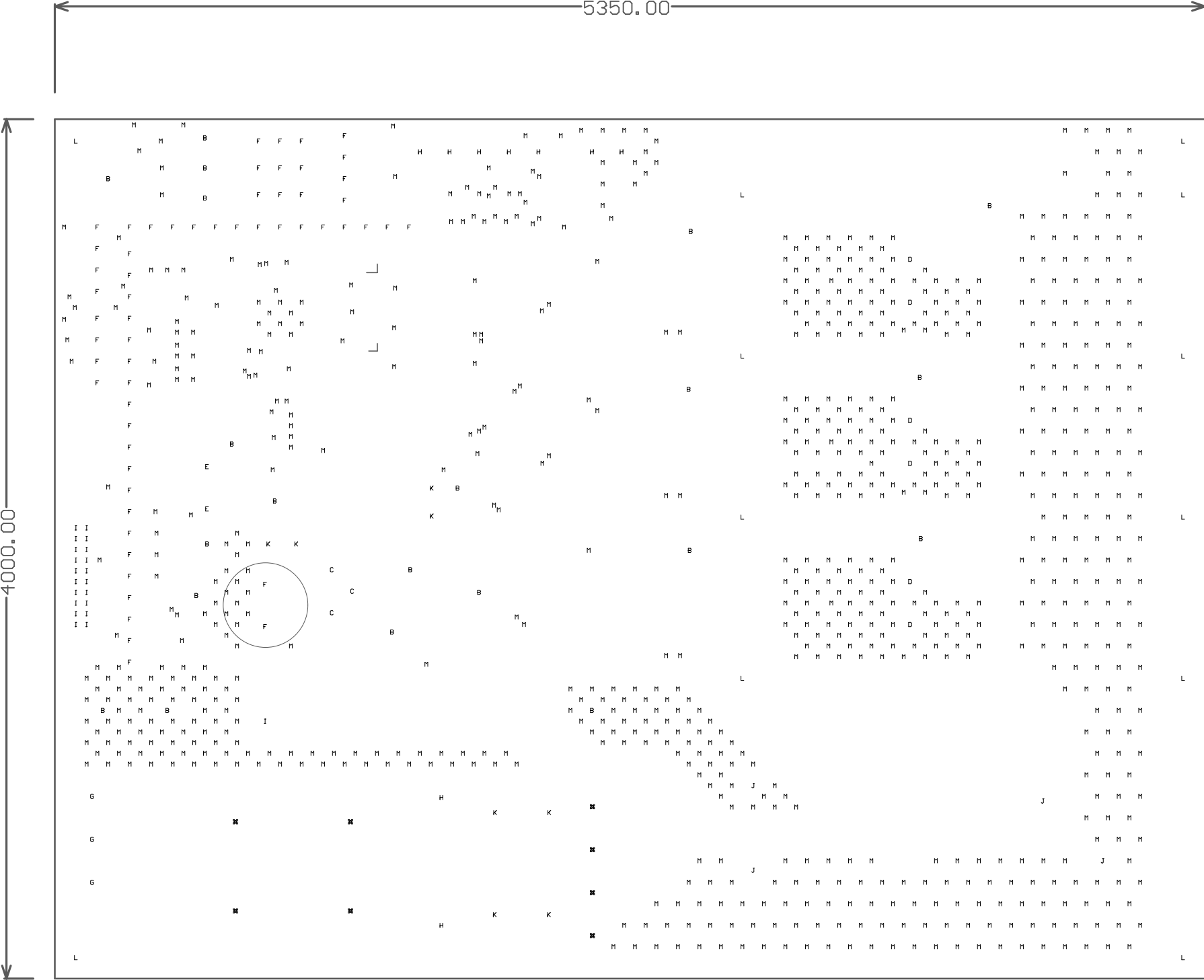

Symbol	Hit Count	Finished Hole Size	Plated	Hole Type	Physical Length	Rout Path Length
M	826	12.00mil (0.305mm)	PTH	Round	—	—
I	21	25.00mil (0.635mm)	PTH	Round	—	—
E	2	27.56mil (0.700mm)	PTH	Round	—	—
F	57	36.00mil (0.914mm)	PTH	Round	—	—
K	8	39.37mil (1.000mm)	PTH	Round	—	—
C	3	40.00mil (1.016mm)	PTH	Round	—	—
H	9	47.24mil (1.200mm)	PTH	Round	—	—
D	6	55.12mil (1.400mm)	PTH	Round	—	—
⌘	8	59.06mil (1.500mm)	PTH	Round	—	—
B	21	63.00mil (1.600mm)	PTH	Round	—	—
G	3	70.87mil (1.800mm)	PTH	Round	—	—
J	4	86.61mil (2.200mm)	PTH	Round	—	—
L	12	125.00mil (3.175mm)	PTH	Round	—	—
	980 Total					

