





1750.00

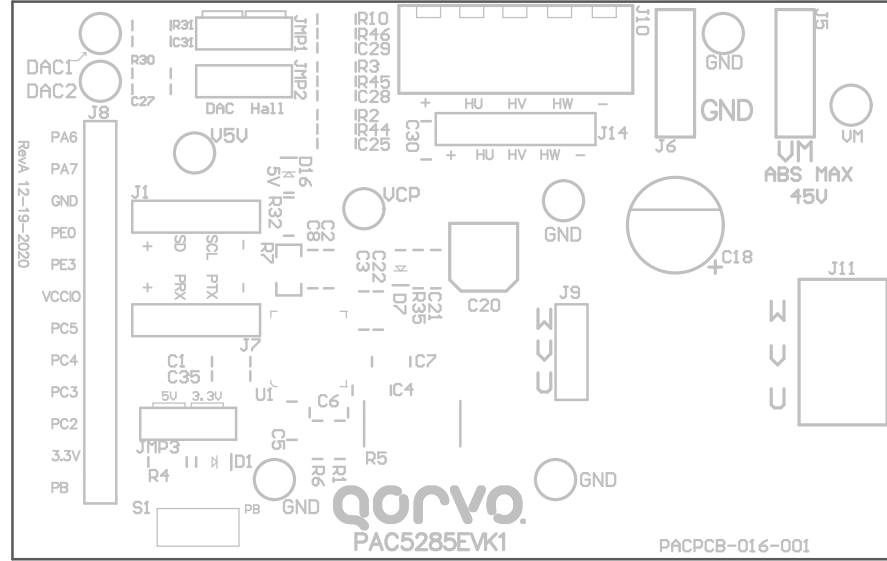

2750.00

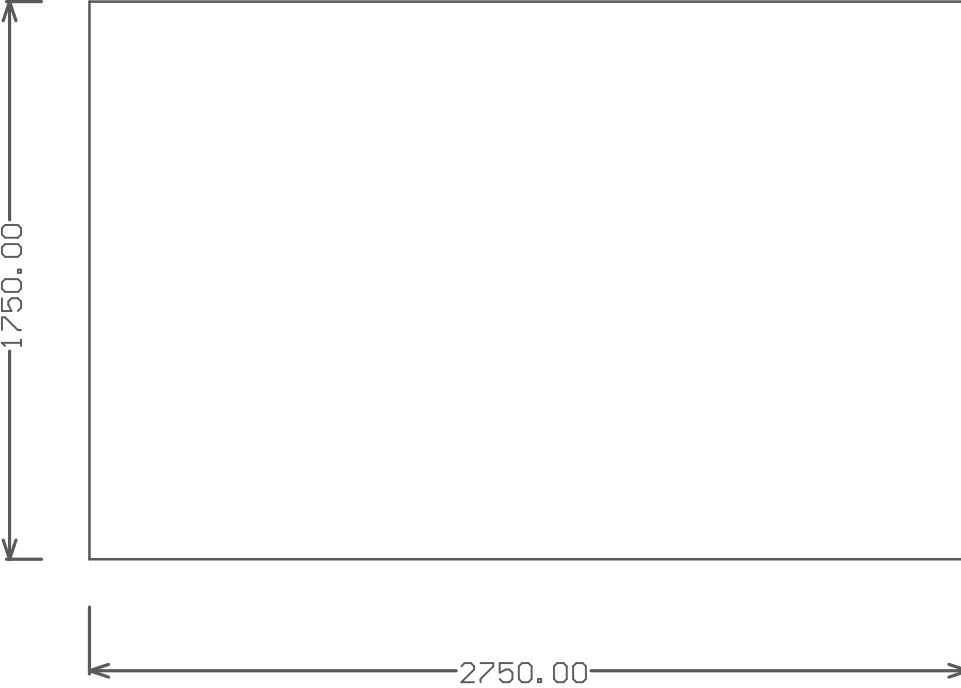

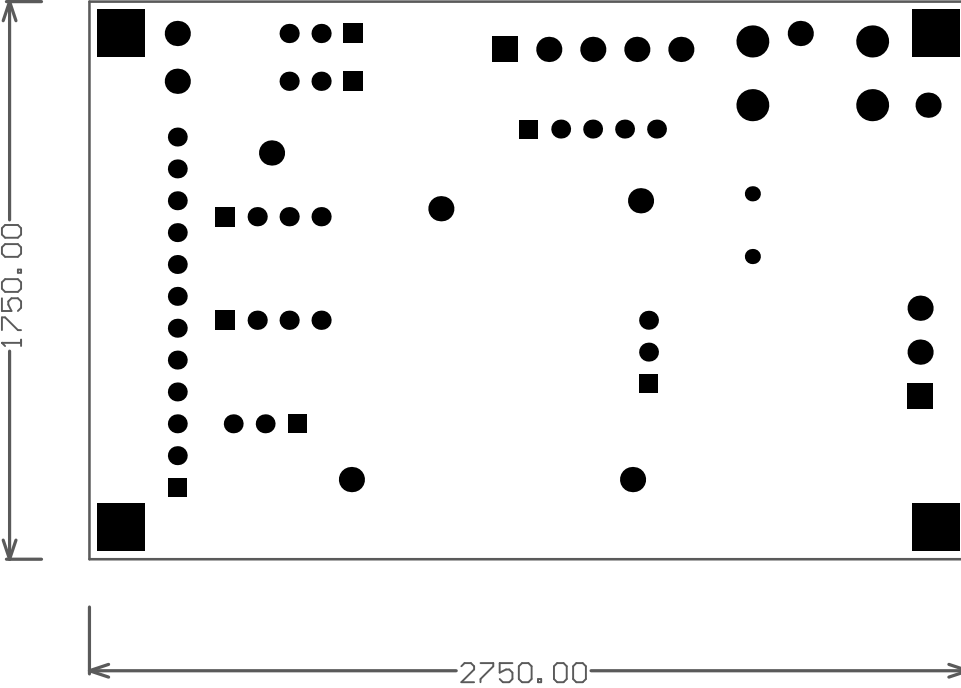

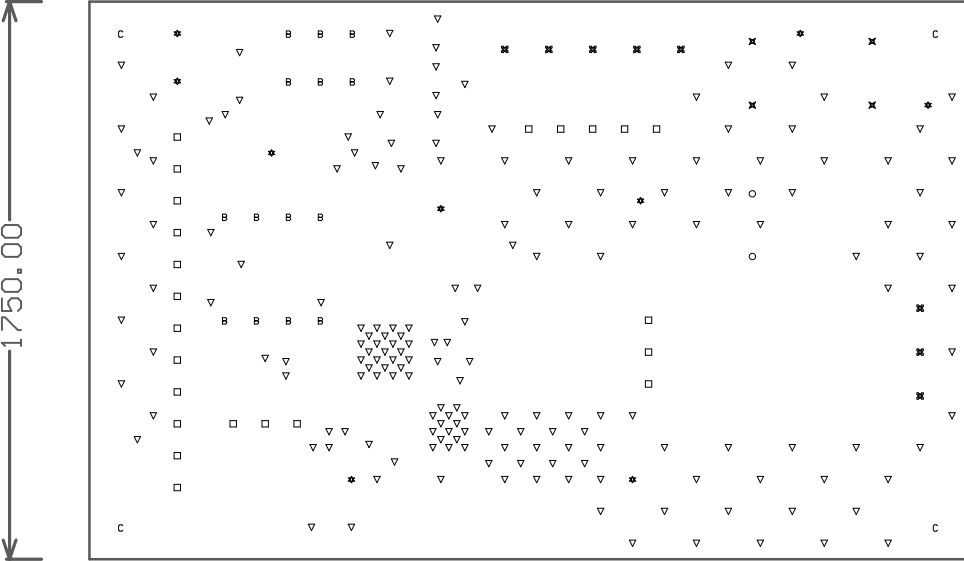

Symbol	Hit Count	Finished Hole Size	Plated	Hole Type	Physical Length	Rout Path Length
○	2	27.56mil (0.700mm)	PTH	Round	—	—
✕	4	55.12mil (1.400mm)	PTH	Round	—	—
C	4	125.00mil (3.175mm)	PTH	Round	—	—
⊠	8	47.24mil (1.200mm)	PTH	Round	—	—
☆	9	63.00mil (1.600mm)	PTH	Round	—	—
B	14	36.00mil (0.914mm)	PTH	Round	—	—
□	23	35.43mil (0.900mm)	PTH	Round	—	—
▽	180	12.00mil (0.305mm)	PTH	Round	—	—
	244 Total					

