
 





TOP OVERLAY

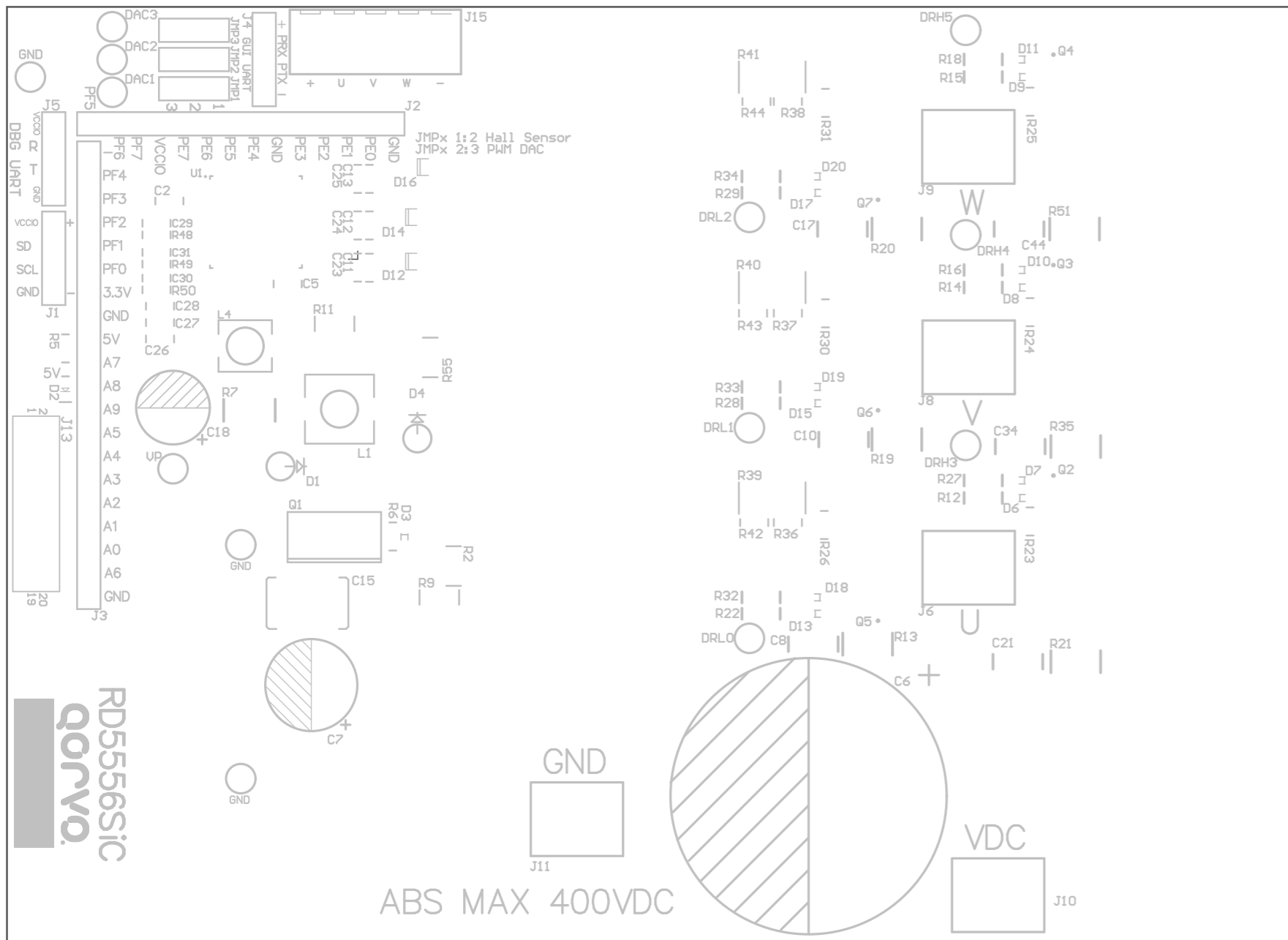



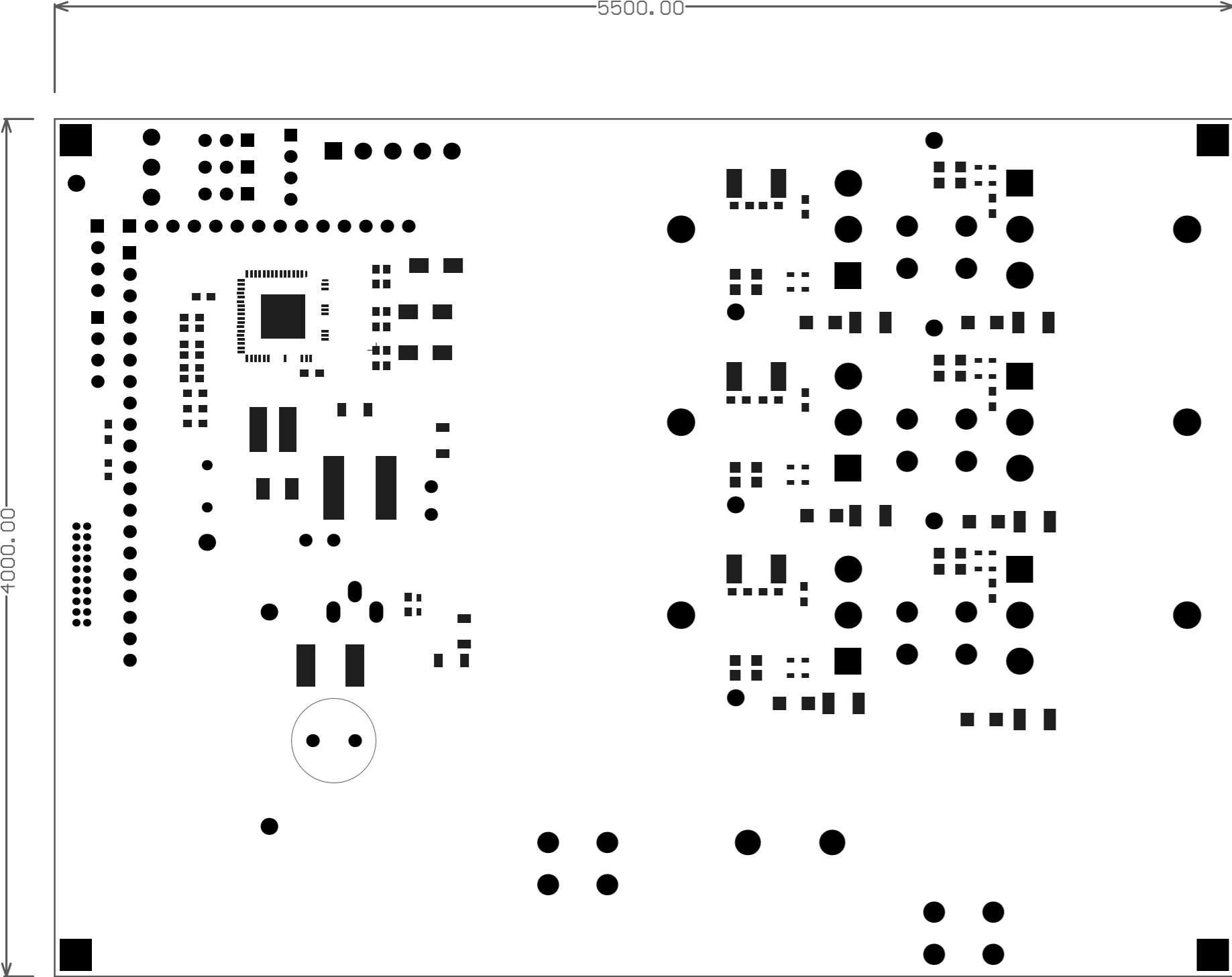

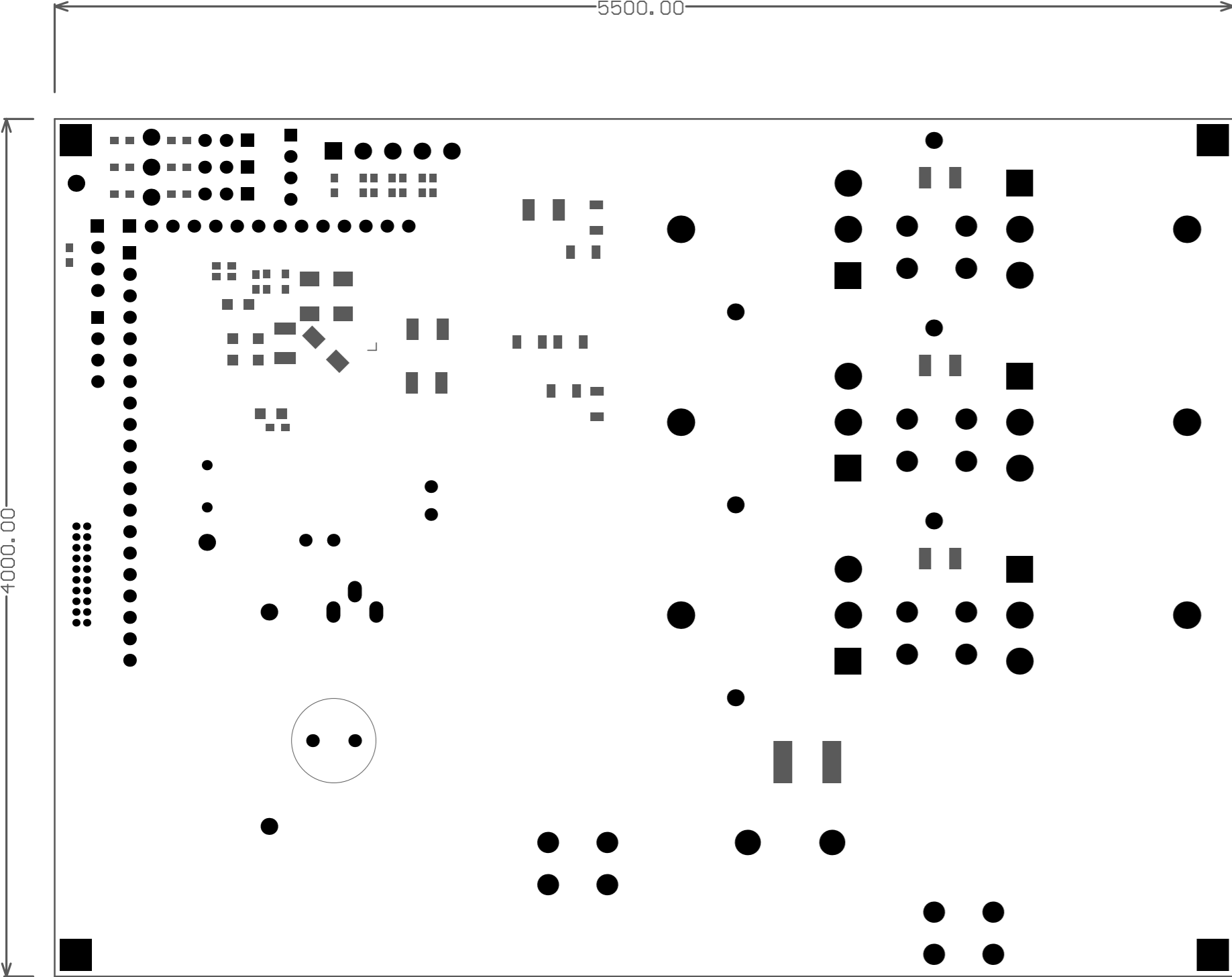

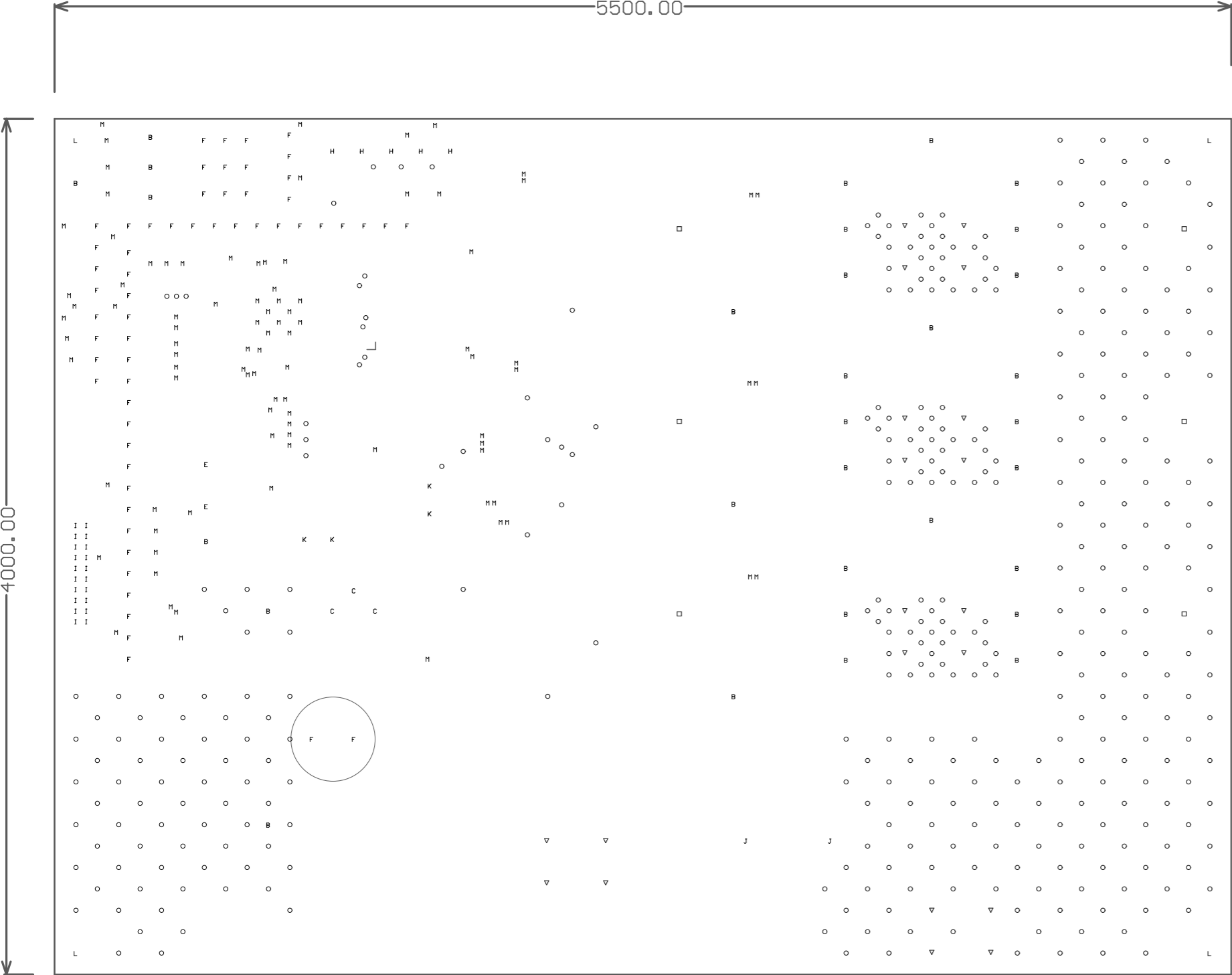

Symbol	Hit Count	Finished Hole Size	Plated	Hole Type	Physical Length	Rout Path Length
M	92	12.00mil (0.305mm)	PTH	Round	—	—
O	379	16.00mil (0.406mm)	PTH	Round	—	—
I	20	25.00mil (0.635mm)	PTH	Round	—	—
E	2	27.56mil (0.700mm)	PTH	Round	—	—
F	57	36.00mil (0.914mm)	PTH	Round	—	—
K	4	39.37mil (1.000mm)	PTH	Round	—	—
C	3	40.00mil (1.016mm)	PTH	Round	—	—
H	5	47.24mil (1.200mm)	PTH	Round	—	—
B	31	63.00mil (1.600mm)	PTH	Round	—	—
▽	20	72.84mil (1.850mm)	PTH	Round	—	—
J	2	86.61mil (2.200mm)	PTH	Round	—	—
L	4	125.00mil (3.175mm)	PTH	Round	—	—
□	6	127.95mil (3.250mm)	PTH	Round	—	—
	625 Total					

